


Technical data sheet

Screw-in spacer clip

Item number: 1366300

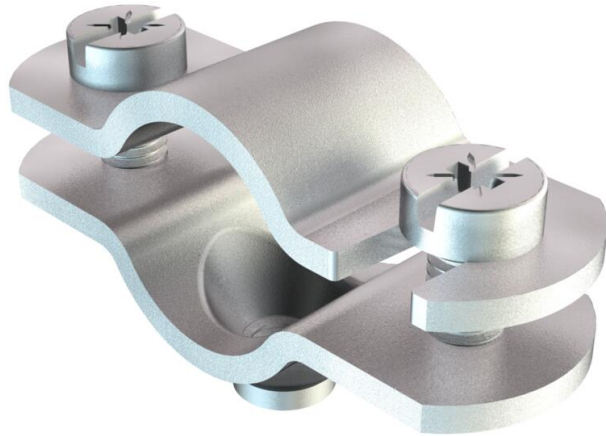

With M6 thread.



St Steel

G Electrogalvanized

Master data

Item number	1366300
Type	731 W 30 G
Description 1	Distance saddle
Description 2	with threaded connection M6
Manufacturer	OBO
Dimension	25-30mm
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	25
Unit of quantity	Piece
Weight	4.06 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0867 kg COe / 1 Piece


Technical data sheet

Screw-in spacer clip

Item number: 1366300



Dimensions

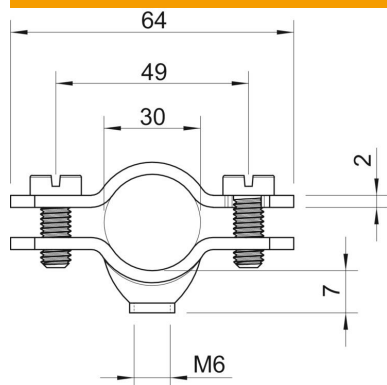

Length	64 mm
Dimension A	64 mm
Dimension B	49 mm
Dimension D	30 mm
Dimension d min.	30 mm
Dimension t	2 mm

Technical data

Number of cables/pipes	1
Version for	Closed
Fastening type	Screw hole
Suitable in fire protection area	no
Halogen-free	no
Plastic-covered	no
Hole size	M6 mm
Material thickness	2 mm
Bolt	M5 x 14
Clamping range D, max.	30 mm
Clamping range D, min.	25 mm
UV-resistant	yes