

# Technical data sheet

## Flat-head screw with internal Torx, steel

Item number: 3164952



Flat head screw with TX 30, according to ISO 7380-1, suitable for fastening cable routes on brackets as well as for the mounting of barrier strips. The rounded head shape provides optimum cable protection. The Torx drive offers optimum force transmission in the screw movement.



**St** Steel

**G** Electrogalvanized

### Master data

|                     |                            |
|---------------------|----------------------------|
| Item number         | 3164952                    |
| Type                | 7380T 6x20 G               |
| Description 1       | Pan head screw             |
| Description 2       | ISO7380-1 with TX30        |
| Manufacturer        | OBO                        |
| Dimension           | M6x20mm                    |
| Material            | Steel                      |
| Surface             | Electrogalvanized          |
| Surface standard    | EN ISO 19598 / EN ISO 4042 |
| Smallest sales unit | 100                        |
| Unit of quantity    | Piece                      |
| Weight              | 0.57 kg                    |
| Weight unit         | kg/100 pc.                 |


# Technical data sheet

Flat-head screw with internal Torx, steel


Item number: 3164952



## Dimensions

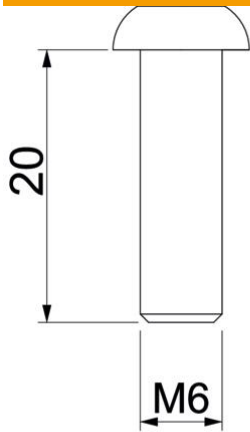

|           |       |
|-----------|-------|
| Dimension | M6x20 |
| Length    | 20 mm |

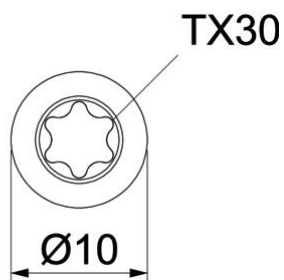

## Technical data

|               |                 |
|---------------|-----------------|
| Thread        | M6              |
| Thread metric | 6               |
| Head shape    | Flat round head |
| Screw system  | Torx            |