

Technical data sheet

Strain relief clip 7902

Item number: 1436023



Fastening clip for strain relief of cables




St	Steel
G	Electrogalvanized

Master data

Item number	1436023
Type	7902 8 G
Description 1	Strain relief clip
Manufacturer	OBO
Dimension	8mm
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.159 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0044 kg COe / 1 Piece

Dimensions

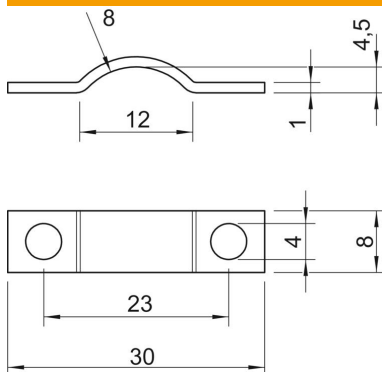

Length	30 mm
Width	8 mm
Height	4.5 mm
Dimension a	12 mm
Dimension b	8 mm
Dimension d	4 mm
Dimension h	4.5 mm
Dimension L	30 mm
Dimension l	23 mm
Dimension R	8 mm
Dimension t	1 mm

Technical data sheet

Strain relief clip 7902

Item number: 1436023



Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Two-lobe
Fastening type	Screw hole
For diameter	8
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Hole size	4 mm
Material thickness	1 mm
Clamping range D, max.	8 mm
Clamping range D, min.	8 mm
UV-resistant	yes