


Technical data sheet

Strain relief clip 7903

Item number: 1437038

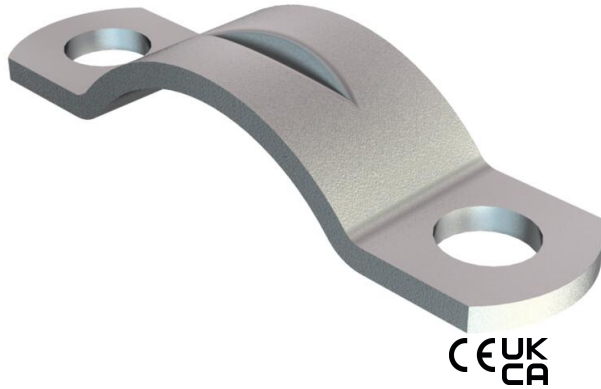


Fastening clip for strain relief of cables

St	Steel
G	Electrogalvanized

Master data

Item number	1437038
Type	7903 9 G
Description 1	Strain relief clip
Manufacturer	OBO
Dimension	9mm
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.244 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0099 kg COe / 1 Piece

Dimensions

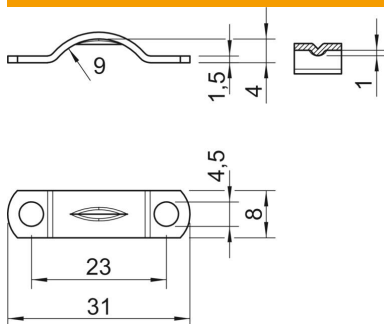

Length	31 mm
Width	8 mm
Height	4 mm
Dimension b	8 mm
Dimension d	4.5 mm
Dimension h	4 mm
Dimension H1 (mm)	1
Dimension L	31 mm
Dimension l	23 mm
Dimension R	9 mm
Dimension t	1.5 mm

Technical data sheet

Strain relief clip 7903

Item number: 1437038



Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Two-lobe
Fastening type	Screw hole
For diameter	9
Suitable in fire protection area	no
Size	III
Halogen-free	yes
Plastic-covered	no
Hole size	4,5 mm
Material thickness	1 mm
Nominal diameter	9 mm
Clamping range D, max.	9 mm
Clamping range D, min.	9 mm
UV-resistant	yes