


Technical data sheet

Strain relief clip 7908

Item number: 1442015

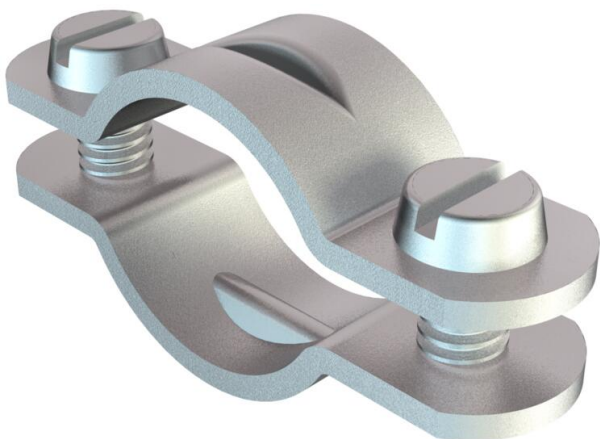

Strain relief clip 11 mm




- St Steel
- G Electrogalvanized

Master data

Item number	1442015
Type	7908 11 G
Description 1	Strain relief clip
Manufacturer	OBO
Dimension	11mm
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.433 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0218 kg COe / 1 Piece

Dimensions

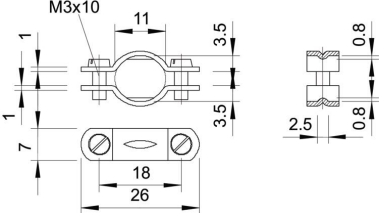

Technical data sheet

Strain relief clip 7908

Item number: 1442015



Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Two-lobe
Fastening type	Screw hole
For diameter	11
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Material thickness	1 mm
Nominal diameter	11 mm
Clamping range D, max.	11 mm
Clamping range D, min.	11 mm
UV-resistant	yes