

Technical data sheet

Bridging cable

Item number: 5331013



- With aluminium cable lugs
- From flexible copper cable 16 mm²
- Coating: Black, chlorinated EM5 natural rubber mixture
- With 1 fastening hole Ø 10.5 mm per attachment side
- With 2 fastening holes Ø 6.5 mm per attachment side
- Suitable for applications outside or inside
- Temperature range –25 °C to +80 °C (moved) and –40 °C to +80 °C (not moved)
- UV-resistant




Cu Copper

Master data

Item number	5331013
Type	853 300
Description 1	Bridging cable
Manufacturer	OBO
Dimension	300mm
Colour	Black
Material	Copper
Smallest sales unit	10
Unit of quantity	Piece
Weight	7.26 kg
Weight unit	kg/100 pc.

Dimensions

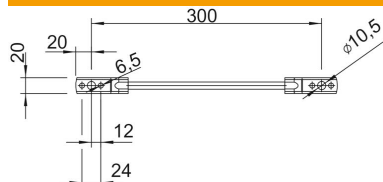

Length	300 mm
Dimension L	300 mm

Technical data sheet

Bridging cable

Item number: 5331013



Technical data

Type of accessory	Bridging cable
Accessories	yes
Spare part	no