

# Technical data sheet

OBO anchor

Item number: 3105032



Hardened steel, shiny without thread.



**St** Steel

| Master data         |                                |  |
|---------------------|--------------------------------|--|
| Item number         | 3105032                        |  |
| Description 1       | OBO plug                       |  |
| Description 2       | knock-in anchor,without thread |  |
| Manufacturer        | OBO                            |  |
| Dimension           | L22mm                          |  |
| Material            | Steel                          |  |
| Smallest sales unit | 200                            |  |
| Unit of quantity    | Piece                          |  |
| Weight              | 0.325 kg                       |  |
| Weight unit         | kg/100 pc.                     |  |


# Technical data sheet

## OBO anchor

Item number: 3105032



### Dimensions

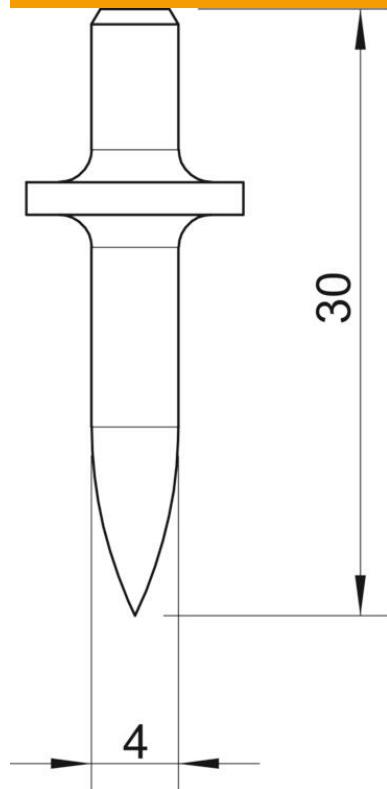

|                  |       |
|------------------|-------|
| Length           | 30 mm |
| Dimension d min. | 4 mm  |
| Dimension L      | 30 mm |

### Technical data

|                 |       |
|-----------------|-------|
| Flange diameter | 10 mm |
| Hardened        | yes   |
| Shank length    | 22    |