

# Technical data sheet

## Screw-in nipple, PG thread, with opening

Item number: 2032163



With open cable entry.

Grip seal to screw into PG thread end to DIN 40430.

With self-sealing cone at the end of the thread, therefore no connection thread sealing ring required.

Protection rating achievable with careful mounting: IP54.  
With open cable entry.



**PE** Polyethylene

### Master data

Item number	2032163
Description 1	Screw-in nipple
Description 2	open version
Manufacturer	OBO
Dimension	PG16
Colour	Light grey; RAL 7035
Material	Polyethylene
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.251 kg
Weight unit	kg/100 pc.


# Technical data sheet

## Screw-in nipple, PG thread, with opening

Item number: 2032163



### Dimensions

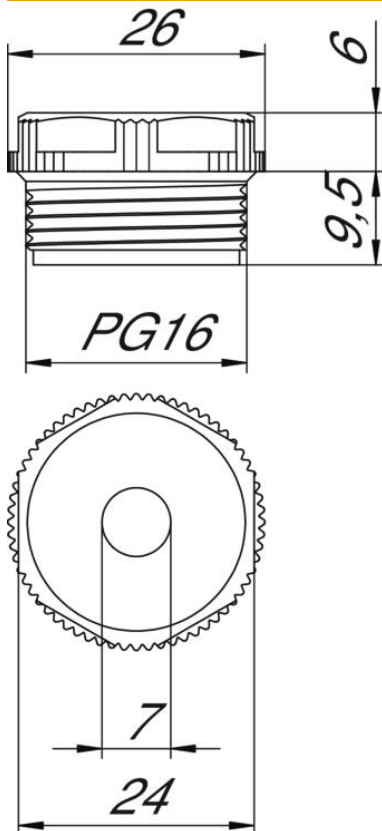

Dimension D	7 mm
Dimension E	26 mm
Dimension L1	9.5 mm
Dimension L2	6 mm

### Technical data

Thread length	9.5 mm
Size	Pg 16
Halogen-free	yes
WAF	24
Protection rating	IP54