

# Technical data sheet

## Multipurpose anchor

Item number: 2348124



Also suitable as a cavity anchor, with collar to prevent slipping. 3 tabs take up the torque.

Required minimum screw length = anchor length + component thickness + 1 x screw Ø.

Withdrawal force applies to wood screws of the largest bolt diameter in concrete of class B25.

Our safety value recommendation: 5x




PA

Polyamide

### Master data

Item number	2348124
Type	910 AZK 8x51
Description 1	All-purpose anchor
Available from	01.05.2020
Manufacturer	OBO
Dimension	8x51
Colour	Light grey
Material	Polyamide
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.106 kg
Weight unit	kg/100 pc.

### Dimensions

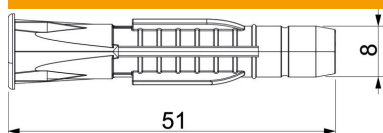

Dimension D	8 mm
Dimension L	51 mm

# Technical data sheet

## Multipurpose anchor

Item number: 2348124



### Technical data

Version for	Universal anchor
Concrete Frat	460
Drill hole diameter, min.	8 mm
Suitable for fastening with cable ties	no
Suitable for gas concrete	no
Suitable for hexagonal wood screw	yes
Plasterboard 12.5 mm Fempf.	90
Hollow brick Hlz12 Frat	320
Wood screws	5-6
Porous calcareous sandstone KSL12 Fempf.	310
With edge	yes
With bolts	no
Porous concrete P2 Fempf.	60
Full brick Mz12 Frat	270