


# Technical data sheet

## Push-fit anchor for Quick clip, type 2957

Item number: 2351650

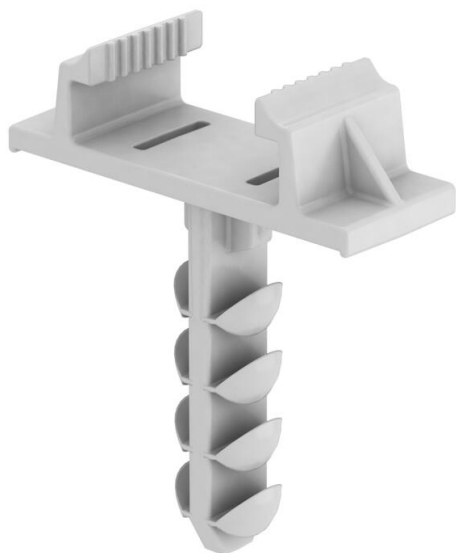

Push-fit anchor suitable for Quick clip, type 2957. The anchor is fixed to the Quick clip by a locking mechanism. Suitable for rapid mounting in concrete walls and masonry.

The anchor is pushed into the hole until the clip makes contact with the surface.



**PA** Polyamide

### Master data

Item number	2351650
Type	910 STQS 6x26
Description 1	Push-fit plug
Description 2	for Quick clip 2957
Manufacturer	OBO
Dimension	6x26mm
Colour	Light grey; RAL 7035
Material	Polyamide
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.11 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0061 kg CO2e / 1 Piece


# Technical data sheet

## Push-fit anchor for Quick clip, type 2957

Item number: 2351650



### Dimensions

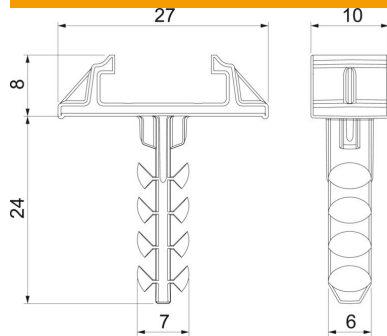

Length	26 mm
Dimension L	26 mm

### Technical data

Version for	Push-fit anchor
Drill hole depth	30 mm
Drill hole diameter, min.	6 mm
Suitable for fastening with cable ties	no
Suitable for gas concrete	yes
Suitable for hexagonal wood screw	no
Halogen-free	yes
With edge	yes
With bolts	no