


Technical data sheet

Earthing pipe clamp, nickel-plated

Item number: 5057507

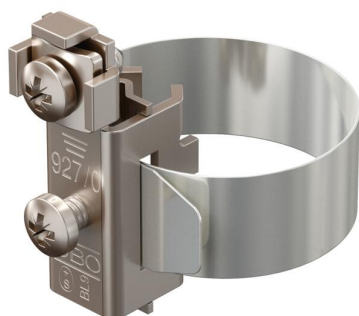

- For pipe Ø 8-22 mm
- Connection options: max. 2 conductors 2.5-10 mm²
- Clamp elements and screws from nickel-plated brass
- Tightening strap from high-grade stainless steel (V2A)

CuZn
37

Brass

N

Nickel-plated

Master data

Item number	5057507
Type	927 0
Description 1	Strip earthing clip
Manufacturer	OBO
Dimension	8-22mm
Material	Brass
Surface	Nickel-plated
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	2.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1124 kg CO2e / 1 Piece


Technical data sheet

Earthing pipe clamp, nickel-plated

Item number: 5057507



Dimensions

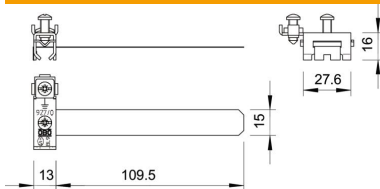

Dimension L 109.5 mm

Technical data

Number of conductors	2
For pipe diameter, max.	22 mm
For pipe diameter, min.	8 mm
Cross-section of cable to be connected, max.	10 mm ²
Cross-section of cable to be connected, min.	2.5 mm ²
Clamping range D, max.	22 mm
Clamping range D, min.	8 mm