

Technical data sheet

Earthing clamp, type 942

Item number: 5038154





- For pipes 1/8–1 1/2" or Ø 8–49 mm
- Connection options: Cables up to 25 mm²
- With connection clip and cylinder bolt M6 x 16 made of brass, nickel-plated
- Clamp cover and base made of copper, nickel-plated

Cu	Copper
N	Nickel-plated

Master data

Item number	5038154
Description 1	Earthing clamp
Manufacturer	OBO
Dimension	44-49mm
Material	Copper
Surface	Nickel-plated
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	10.54 kg
Weight unit	kg/100 pc.

Dimensions

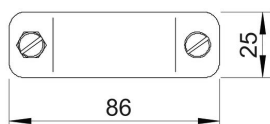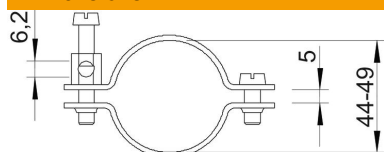

Dimension A	86 mm
Dimension b	25 mm
Dimension X	5 mm

Technical data sheet

Earthing clamp, type 942

Item number: 5038154



Technical data

Number of conductors	1
Cross-section of cable to be connected, max.	25 mm ²
Cross-section of cable to be connected, min.	0 mm ²
Clamping range D	1 1/2
Clamping range D, max.	49 mm
Clamping range D, min.	44 mm