


# Technical data sheet

## Tension jack G

Item number: 5300061

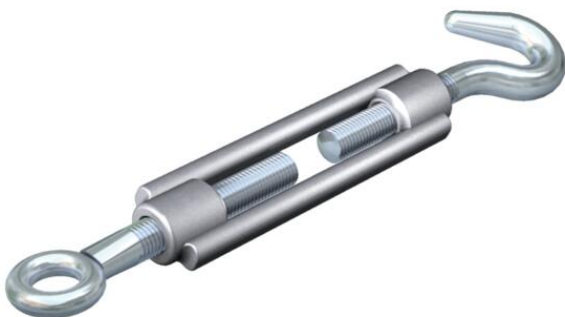

With hook and eye, to DIN 1480.



- St** Steel
- G** Electrogalvanized

| Master data         |                            |  |
|---------------------|----------------------------|--|
| Item number         | 5300061                    |  |
| Description 1       | Tensioner                  |  |
| Manufacturer        | OBO                        |  |
| Dimension           | M12                        |  |
| Material            | Steel                      |  |
| Surface             | Electrogalvanized          |  |
| Surface standard    | EN ISO 19598 / EN ISO 4042 |  |
| Smallest sales unit | 5                          |  |
| Unit of quantity    | Piece                      |  |
| Weight              | 53 kg                      |  |
| Weight unit         | kg/100 pc.                 |  |


# Technical data sheet

## Tension jack G

Item number: 5300061



### Dimensions

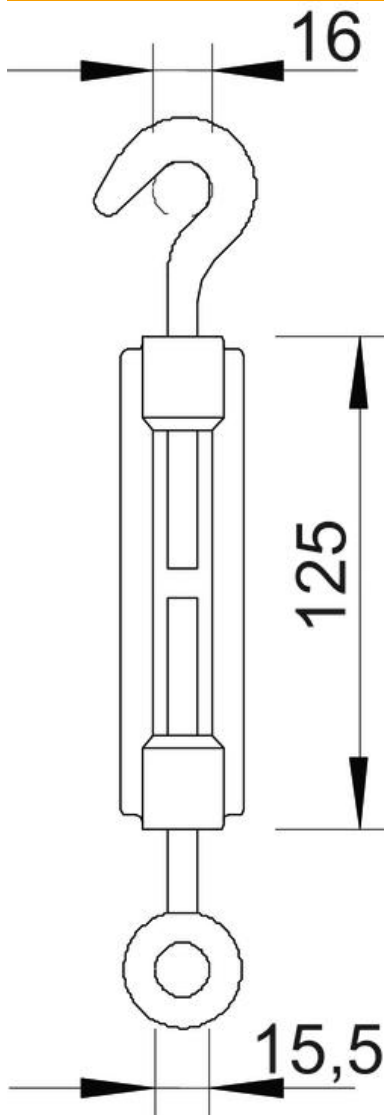

|             |         |
|-------------|---------|
| Dimension A | 16 mm   |
| Dimension B | 15.5 mm |
| Dimension C | 125 mm  |

### Technical data

|                          |        |
|--------------------------|--------|
| Breaking load            | 7 kN   |
| Thread                   | M12    |
| Length of clamping nut C | 125 mm |
| Span width               | 85 mm  |