

# Technical data sheet

## Tension jack A4

Item number: 5300120



With hook and eye, to DIN 1480.



**A4** Stainless steel

**2B** Bright, treated

### Master data

|                                    |                          |
|------------------------------------|--------------------------|
| Item number                        | 5300120                  |
| Type                               | 945 M6 A4                |
| Description 1                      | Tensioner                |
| Manufacturer                       | OBO                      |
| Dimension                          | M6                       |
| Material                           | Stainless steel          |
| Surface                            | Bright, treated          |
| Surface standard                   |                          |
| Smallest sales unit                | 5                        |
| Unit of quantity                   | Piece                    |
| Weight                             | 10.5 kg                  |
| Weight unit                        | kg/100 pc.               |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,5058 kg CO2e / 1 Piece |


# Technical data sheet

## Tension jack A4

Item number: 5300120



### Dimensions

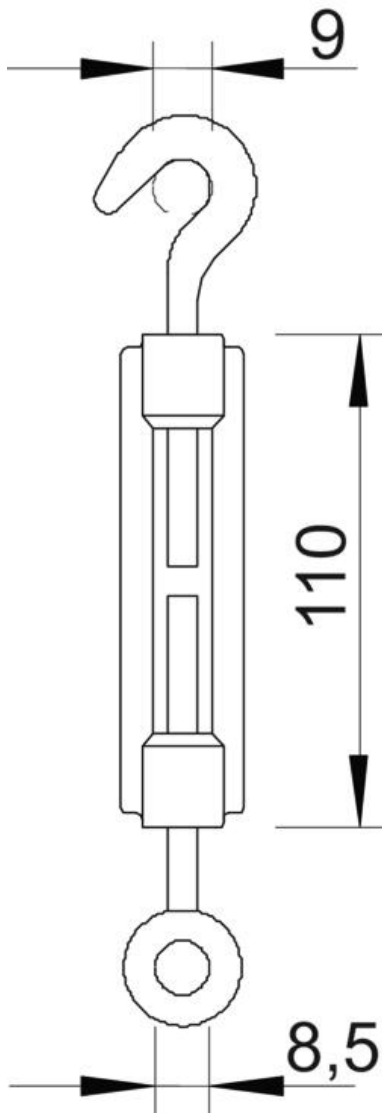

|             |        |
|-------------|--------|
| Dimension A | 9 mm   |
| Dimension B | 8.5 mm |
| Dimension C | 110 mm |

### Technical data

|                          |        |
|--------------------------|--------|
| Breaking load            | 2 kN   |
| Thread                   | M6     |
| Length of clamping nut C | 110 mm |
| Span width               | 80 mm  |