

Technical data sheet

Earthing strap, type 950

Item number: 5050154



- For pipes Ø 1/4"-2"
 - Connection options: conductors to 35 mm² or round conductors to Ø 6 mm
 - With captive pressure strip, 2 cylinder bolts M6 x 16 and 1 hex-head screw M6 x 16
- from galvanised steel, top and bottom part of clamp from die-cast zinc

Zn	Die-cast zinc
G	Electrogalvanized

Master data

Item number	5050154
Type	950 Z 1 1/2
Description 1	Earthing clamp
Description 2	for round conductor
Manufacturer	OBO
Dimension	1 1/2"
Material	Die-cast zinc
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	10
Unit of quantity	Piece
Weight	10.41 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4348 kg CO2e / 1 Piece


Technical data sheet

Earthing strap, type 950

Item number: 5050154



Dimensions

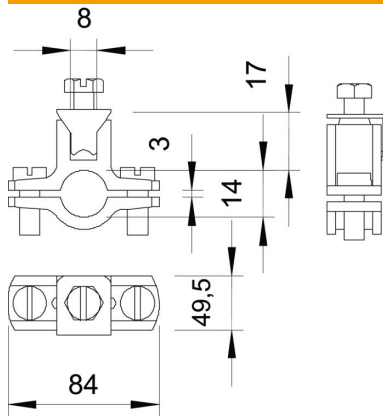

Dimension A	84 mm
Dimension D	49.5 mm
Dimension X	3 mm

Technical data

Number of conductors	1
Cross-section of cable to be connected, max.	35 mm ²
Cross-section of cable to be connected, min.	0 mm ²
Clamping range D	1 1/2
Clamping range D, max.	49.5 mm
Clamping range D, min.	46.5 mm