

Technical data sheet

Earthing strap, type 950

Item number: 5050030



- For pipes Ø 1/4"-2"
 - Connection options: conductors to 35 mm² or round conductors to Ø 6 mm
 - With captive pressure strip, 2 cylinder bolts M6 x 16 and 1 hex-head screw M6 x 16
- from galvanised steel, top and bottom part of clamp from die-cast zinc

Zn	Die-cast zinc
G	Electrogalvanized

Master data

Item number	5050030
Type	950 Z 1/4
Description 1	Earthing clamp
Description 2	for round conductor
Manufacturer	OBO
Dimension	1/4"
Material	Die-cast zinc
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	10
Unit of quantity	Piece
Weight	5.83 kg
Weight unit	kg/100 pc.


Technical data sheet

Earthing strap, type 950

Item number: 5050030



Dimensions

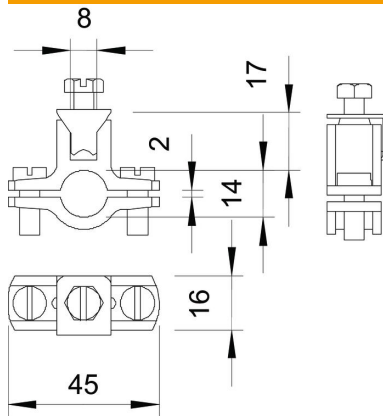

Dimension A	45 mm
Dimension D	14 mm
Dimension X	2 mm

Technical data

Number of conductors	1
Cross-section of cable to be connected, max.	35 mm ²
Cross-section of cable to be connected, min.	0 mm ²
Clamping range D	1/4
Clamping range D, max.	14 mm
Clamping range D, min.	12 mm