

# Technical data sheet

## Steel wire tensioning rope A4

Item number: 5303179



Cable Ø 2–6 mm: round-stranded cable 6 x 7 according to DIN 3055.  
Cable Ø 8–10 mm: round-stranded cable 6 x 19 according to DIN 3060.  
Minimum break force 1,770 N/mm<sup>2</sup>.



|    |                 |
|----|-----------------|
| A4 | Stainless steel |
| 2B | Bright, treated |

### Master data

|                     |                             |
|---------------------|-----------------------------|
| Item number         | 5303179                     |
| Type                | 957 2 A4                    |
| Description 1       | Steel wire tensioning cable |
| Description 2       | with hemp core              |
| Manufacturer        | OBO                         |
| Dimension           | 2                           |
| Material            | Stainless steel             |
| Surface             | Bright, treated             |
| Surface standard    |                             |
| Smallest sales unit | 50                          |
| Unit of quantity    | Metre                       |
| Weight              | 1.43 kg                     |
| Weight unit         | kg/100 m                    |


# Technical data sheet

## Steel wire tensioning rope A4


Item number: 5303179



### Dimensions

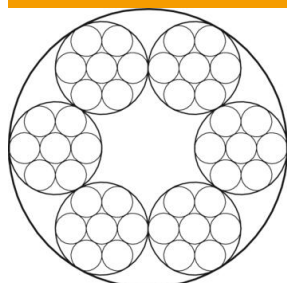

6x7

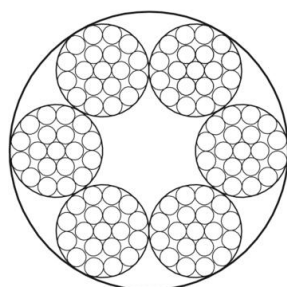

6x19

### Technical data

|                |         |
|----------------|---------|
| Breaking load  | 2.35 kN |
| in rings       | 50 m    |
| Cable diameter | 2 mm    |