

Technical data sheet

Steel wire tensioning rope A4

Item number: 5303182



Cable Ø 2–6 mm: round-stranded cable 6 x 7 according to DIN 3055.
Cable Ø 8–10 mm: round-stranded cable 6 x 19 according to DIN 3060.
Minimum break force 1,770 N/mm².



A4	Stainless steel
2B	Bright, treated

Master data

Item number	5303182
Type	957 3 A4
Description 1	Steel wire tensioning cable
Description 2	with hemp core
Manufacturer	OBO
Dimension	3
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	50
Unit of quantity	Metre
Weight	3.22 kg
Weight unit	kg/100 m


Technical data sheet

Steel wire tensioning rope A4


Item number: 5303182



Dimensions

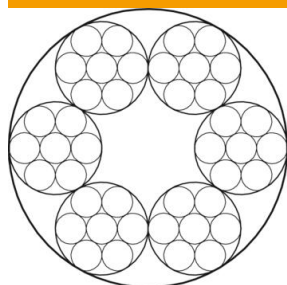

6x7

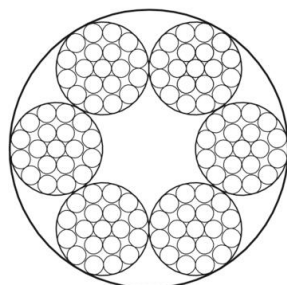

6x19

Technical data

Breaking load	5.29 kN
in rings	50 m
Cable diameter	3 mm