

Technical data sheet

Ceiling bracket FT

Item number: 6363907



Suspension bracket for cable support systems.



St Steel

FT Hot-dip galvanised

Master data

Item number	6363907
Type	AHB 150 FT
Description 1	Suspension bracket
Description 2	flat steel
Manufacturer	OBO
Dimension	B150mm
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	87 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,8691 kg CO2e / 1 Piece


Technical data sheet

Ceiling bracket FT

Item number: 6363907



Dimensions

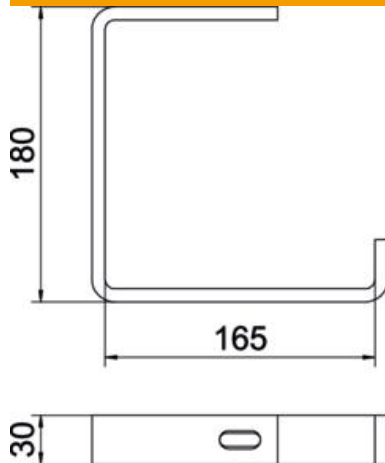

Length	30 mm
Width	181 mm
Height	180 mm
Dimension B	165 mm

Technical data

Version for	Suspension bracket (C clamp)
F in kN ceiling	0.6 kN
Maintain electrical functions	no
for width max.	150 mm
for width min.	150
Suitable for metric threaded rod	10
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for tray/ladder width	150 mm
Hole diameter	11 mm
Material thickness	8 mm
Tray fastening	Screw-on
Adjustable	no