


Technical data sheet

Ceiling bracket 13 FT

Item number: 6363939



Suspension bracket for cable support systems to fasten directly under the ceiling or as a suspension with threaded rods M10.

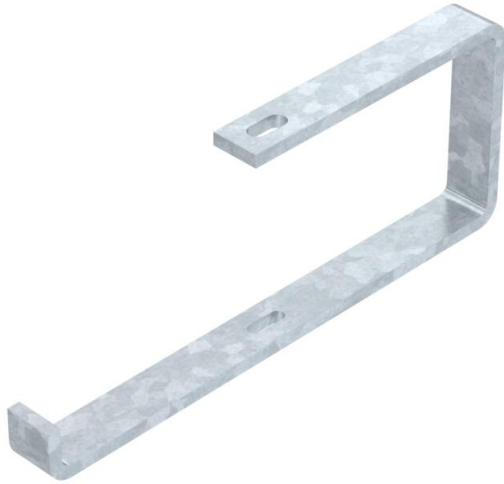

St	Steel
FT	Hot-dip galvanised

Master data

Item number	6363939
Type	AHB 300 13 FT
Description 1	Suspension bracket
Description 2	flat steel
Manufacturer	OBO
Dimension	B300mm
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	120 kg
Weight unit	kg/100 pc.

 
Technical data sheet

Ceiling bracket 13 FT

Item number: 6363939



Dimensions



Width	331 mm
Height	130 mm
Maß W	315 mm

Technical data

Version for	Suspension bracket (C clamp)
F in kN ceiling	0.35 kN
Maintain electrical functions	no
for width max.	300 mm
for width min.	300
Suitable for metric threaded rod	10
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for tray/ladder width	300 mm
Hole diameter	11 mm
Material thickness	8 mm
Tray fastening	Screw-on
Adjustable	no