

# Technical data sheet

## Suspension bracket 50 FT

Item number: 6066505



Suspension bracket for chain or steel wire tensioning rope fastening of the luminaire support rail, type LTS 50, and the AZ small duct, type AZK 50.



|           |                |
|-----------|----------------|
| <b>St</b> | Steel          |
| <b>F</b>  | Hot galvanized |

### Master data

|                                   |                         |
|-----------------------------------|-------------------------|
| Item number                       | 6066505                 |
| Description 1                     | Suspension clamp        |
| Description 2                     | for AZK 50 and LTS 50   |
| Manufacturer                      | OBO                     |
| Colour                            | zinc                    |
| Material                          | Steel                   |
| Surface                           | Hot galvanized          |
| Surface standard                  | DIN 267, Teil 10        |
| Smallest sales unit               | 50                      |
| Unit of quantity                  | Piece                   |
| Weight                            | 1.985 kg                |
| Weight unit                       | kg/100 pc.              |
| CO Footprint (GWP) Cradle-to-Gate | 0,0561 kg COe / 1 Piece |


# Technical data sheet

## Suspension bracket 50 FT

Item number: 6066505



### Dimensions

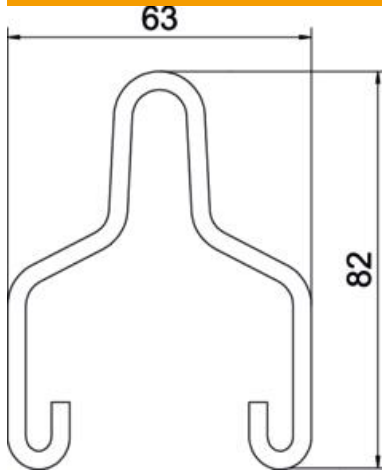

|        |         |
|--------|---------|
| Width  | 62.8 mm |
| Height | 82.3 mm |

### Technical data

|                               |         |
|-------------------------------|---------|
| F in kN                       | 0.35 kN |
| Maintain electrical functions | no      |
| Material thickness            | 4 mm    |
| Rustproof steel, pickled      | no      |
| Hinged                        | no      |
| Adjustable                    | no      |