


Technical data sheet

Quick clip, aluminium

Item number: 2149925

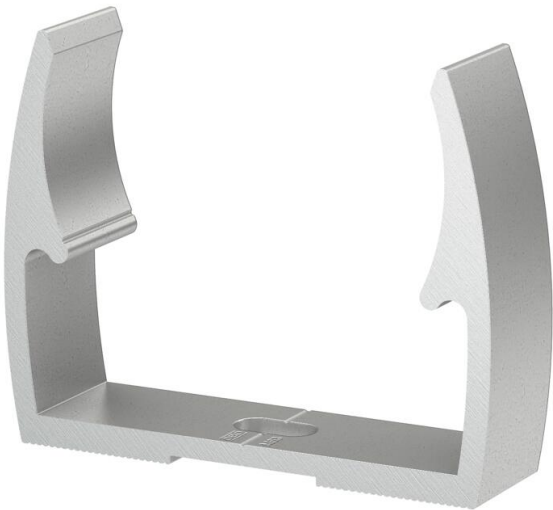

OBO Quick clip, type ALQ M, for all metric ALU pipe systems, as well as light-duty and heavy-duty insulation pipes. Suitable for mounting the OBO pipe system, material: aluminium. Pipe centring aids allow optimal attachment of the pipe and automatically turn the clip into the correct position.

Slot for side alignment during mounting with wood screw or knock-in anchor.

Recommended fastening spacing 50–60 cm.



Alu Aluminium

Master data		
Item number	2149925	
Type	ALQ M25	
Description 1	Quick clip	
Manufacturer	OBO	
Dimension	M25	
Material	Aluminium	
Smallest sales unit	100	
Unit of quantity	Piece	
Weight	1.11 kg	
Weight unit	kg/100 pc.	
CO Footprint (GWP) Cradle-to-Gate	0,1856 kg COe / 1 Piece	


Technical data sheet

Quick clip, aluminium

Item number: 2149925



Dimensions

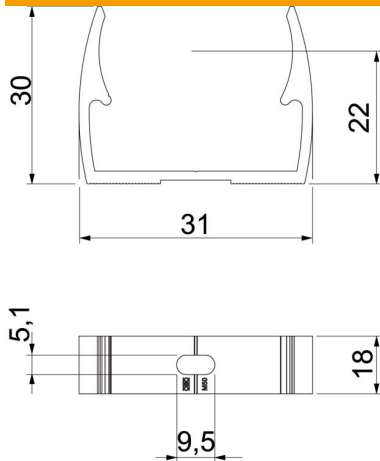

Dimension A	31 mm
Dimension B	18 mm
Dimension E	5.1 mm
Dimension F	9.5 mm
Dimension h	22 mm
Dimension H	30 mm

Technical data

Expandable	no
Number of cables/pipes	1
Pull-out value	90 N
Fastening type	Screw hole
Closed	no
Halogen-free	no
With inlay	no
Nominal size	25
Clamping range D, max.	25 mm
Clamping range D, min.	25 mm
UV-resistant	yes