


Technical data sheet

Quick clip, aluminium

Item number: 2149963

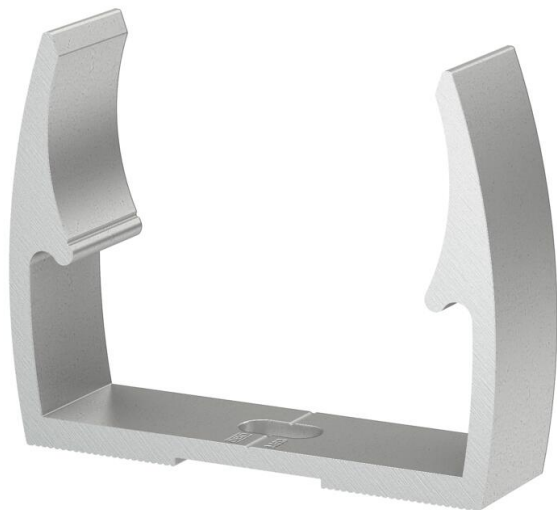

OBO Quick clip, type ALQ M, for all metric ALU pipe systems, as well as light-duty and heavy-duty insulation pipes. Suitable for mounting the OBO pipe system, material: aluminium. Pipe centring aids allow optimal attachment of the pipe and automatically turn the clip into the correct position.

Slot for side alignment during mounting with wood screw or knock-in anchor.

Recommended fastening spacing 50–60 cm.



Alu

Aluminium

Master data

Item number	2149963
Type	ALQ M63
Description 1	Quick clip
Manufacturer	OBO
Dimension	M63
Material	Aluminium
Smallest sales unit	20
Unit of quantity	Piece
Weight	3.34 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,5461 kg COe / 1 Piece


Technical data sheet

Quick clip, aluminium

Item number: 2149963



Dimensions

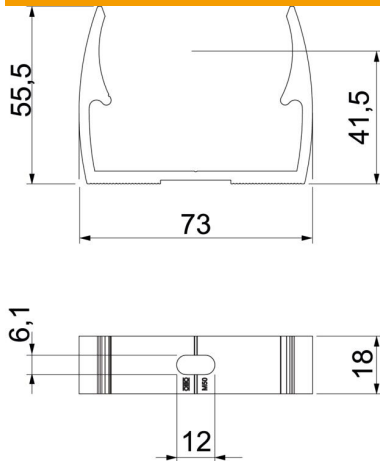

Dimension A	73 mm
Dimension B	18 mm
Dimension E	6.1 mm
Dimension F	12 mm
Dimension h	41.5 mm
Dimension H	55.5 mm

Technical data

Expandable	no
Number of cables/pipes	1
Pull-out value	70 N
Fastening type	Screw hole
Closed	no
Halogen-free	no
With inlay	no
Nominal size	63
Clamping range D, max.	63 mm
Clamping range D, min.	63 mm
UV-resistant	yes