

Technical data sheet

Connection cable – AL EX ISG

Item number: 5240102



UV-resistant connection cable (copper 25 mm²) for mounting the OBO Ex spark gap, type EX ISG, on insulating flanges and insulating pieces. With cable shoe for M10 bolts on both sides, on one side with M10 bolt, nuts and spring ring.

Cu

Copper

Master data		
	Item number	5240102
	Type	AL EX ISG 100
	Description 1	Connecting cable
	Description 2	for EX ISG H
	Manufacturer	OBO
	Dimension	100mm
	Material	Copper
	Smallest sales unit	1
	Unit of quantity	Piece
	Weight	9.6 kg
	Weight unit	kg/100 pc.
	CO2 Footprint (GWP) Cradle-to-Gate	0,4401 kg CO2e / 1 Piece


Technical data sheet

Connection cable – AL EX ISG

Item number: 5240102



Dimensions

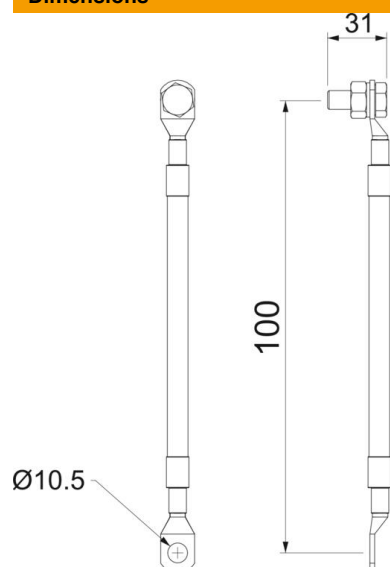

Dimension	100
-----------	-----

Technical data

Connecting cable length	0.1 m
Accessories	yes
Spare part	no
Type of accessory, accessory for surge protection, energy technology	Connection cable