

# Technical data sheet

## Spacer clip 732 A2

Item number: 1362632



Spacer clip for the installation of pipes and cables on walls, ceiling and floors. With self-locking upper part. Surfaces G and FT from a clip size of 20 are suitable for installation with a nail device or a bolt-firing tool.

Approved for the maintenance of electrical function according to DIN 4102 Part 12, maintenance of electrical function classes E30 to E90.



A2 Stainless steel

### Master data

|                                   |                             |
|-----------------------------------|-----------------------------|
| Item number                       | 1362632                     |
| Type                              | ASG 732 14 A2               |
| Description 1                     | Distance saddle             |
| Description 2                     | with threaded connection M6 |
| Manufacturer                      | OBO                         |
| Dimension                         | 12-14mm                     |
| Material                          | Stainless steel             |
| Smallest sales unit               | 25                          |
| Unit of quantity                  | Piece                       |
| Weight                            | 1.859 kg                    |
| Weight unit                       | kg/100 pc.                  |
| CO Footprint (GWP) Cradle-to-Gate | 0,1725 kg COe / 1 Piece     |


# Technical data sheet

## Spacer clip 732 A2

Item number: 1362632



### Dimensions

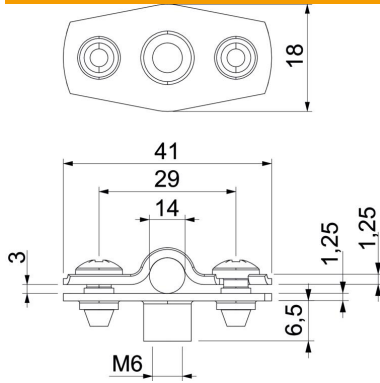

|                   |       |
|-------------------|-------|
| Dimension A       | 41 mm |
| Dimension B       | 29 mm |
| Dimension b       | 18 mm |
| Dimension D       | 14 mm |
| Dimension d max.  | 14 mm |
| Dimension d min.  | 12 mm |
| Dimension H1      | 12 mm |
| Dimension t1 (mm) | 1.25  |
| Dimension t2 (mm) | 1.25  |
| Dimension x       | 3 mm  |

### Technical data

|                                  |         |
|----------------------------------|---------|
| Distance to the wall             | yes     |
| Number of cables/pipes           | 1       |
| Version for                      | Closed  |
| For diameter                     | 12 - 14 |
| Suitable in fire protection area | yes     |
| Halogen-free                     | yes     |
| Plastic-covered                  | no      |
| Material thickness               | 1.25 mm |
| Clamping range D, max.           | 14 mm   |
| Clamping range D, min.           | 12 mm   |
| UV-resistant                     | yes     |