

Technical data sheet

Spacer clip 732 A4

Item number: 1362467



Spacer clip for the installation of pipes and cables on walls, ceilings and floors. With self-locking cover. Fastening via attachment piece with internal thread.

Approved for the maintenance of electrical function according to DIN 4102 Part 12, maintenance of electrical function classes E 30 to E 90.



A4 Stainless steel

Master data		
Item number	1362467	
Type	ASG 732 17 A4	
Description 1	Distance saddle	
Description 2	with threaded connection M6	
Manufacturer	OBO	
Dimension	14-17mm	
Material	Stainless steel	
Smallest sales unit	25	
Unit of quantity	Piece	
Weight	2.035 kg	
Weight unit	kg/100 pc.	
CO Footprint (GWP) Cradle-to-Gate	0,1842 kg COe / 1 Piece	


Technical data sheet

Spacer clip 732 A4

Item number: 1362467



Dimensions

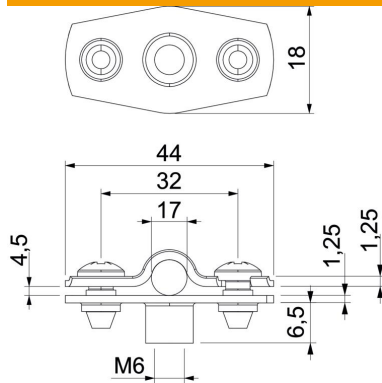

Dimension A	44 mm
Dimension B	32 mm
Dimension b	18 mm
Dimension D	17 mm
Dimension d max.	17 mm
Dimension d min.	14 mm
Dimension H1	12 mm
Dimension t1 (mm)	1.25
Dimension t2 (mm)	1.25
Dimension x	4.5 mm

Technical data

Distance to the wall	yes
Number of cables/pipes	1
Version for	Closed
Fastening type	Threaded connection
For diameter	14 - 17
Suitable in fire protection area	yes
Halogen-free	yes
Plastic-covered	no
Material thickness	1.25 mm
Clamping range D, max.	17 mm
Clamping range D, min.	14 mm
UV-resistant	yes