

Technical data sheet

Spacer clip 732 A2

Item number: 1362640



Spacer clip for the installation of pipes and cables on walls, ceiling and floors. With self-locking upper part. Surfaces G and FT from a clip size of 20 are suitable for installation with a nail device or a bolt-firing tool.

Approved for the maintenance of electrical function according to DIN 4102 Part 12, maintenance of electrical function classes E30 to E90.



A2 Stainless steel

Master data		
Item number	1362640	
Type	ASG 732 30 A2	
Description 1	Distance saddle	
Description 2	with threaded connection M6	
Manufacturer	OBO	
Dimension	25-30mm	
Material	Stainless steel	
Smallest sales unit	20	
Unit of quantity	Piece	
Weight	3.321 kg	
Weight unit	kg/100 pc.	
CO Footprint (GWP) Cradle-to-Gate	0,277 kg COe / 1 Piece	


Technical data sheet

Spacer clip 732 A2

Item number: 1362640



Dimensions

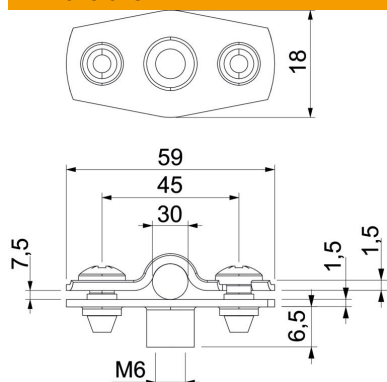

Dimension A	59 mm
Dimension B	45 mm
Dimension b	18 mm
Dimension D	30 mm
Dimension d max.	30 mm
Dimension d min.	25 mm
Dimension H1	12 mm
Dimension t1 (mm)	1.5
Dimension t2 (mm)	1.5
Dimension x	7.5 mm

Technical data

Distance to the wall	yes
Number of cables/pipes	1
Version for	Closed
For diameter	25 - 30
Suitable in fire protection area	yes
Halogen-free	yes
Plastic-covered	no
Material thickness	1.5 mm
Clamping range D, max.	30 mm
Clamping range D, min.	25 mm
UV-resistant	yes