


Technical data sheet

Spacer clip 732 A4

Item number: 1362474

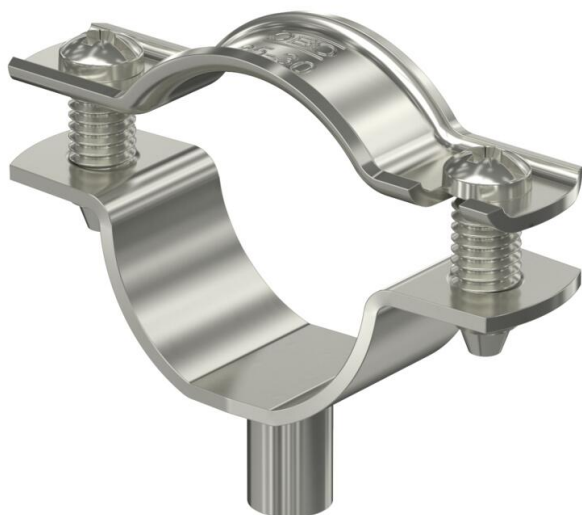

Spacer clip for the installation of pipes and cables on walls, ceilings and floors. With self-locking cover. Fastening via attachment piece with internal thread.

Approved for the maintenance of electrical function according to DIN 4102 Part 12, maintenance of electrical function classes E 30 to E 90.



A4 Stainless steel

Master data

Item number	1362474
Type	ASG 732 30 A4
Description 1	Distance saddle
Description 2	with threaded connection M6
Manufacturer	OBO
Dimension	25-30mm
Material	Stainless steel
Smallest sales unit	20
Unit of quantity	Piece
Weight	3.37 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,1903 kg COe / 1 Piece

