

# Technical data sheet

## Spacer clip 733 A4

Item number: 1362912



Spacer clip for the installation of pipes and cables on walls, ceilings and floors.  
With self-locking cover. Fastening via slot.

Approved for the maintenance of electrical function according to DIN 4102 Part 12, maintenance of electrical function classes E 30 to E 90.



**A4** Stainless steel

| Master data                       |                         |  |
|-----------------------------------|-------------------------|--|
| Item number                       | 1362912                 |  |
| Type                              | ASL 733 17 A4           |  |
| Description 1                     | Distance saddle         |  |
| Description 2                     | with slot               |  |
| Manufacturer                      | OBO                     |  |
| Dimension                         | 14-17mm                 |  |
| Material                          | Stainless steel         |  |
| Smallest sales unit               | 25                      |  |
| Unit of quantity                  | Piece                   |  |
| Weight                            | 2.139 kg                |  |
| Weight unit                       | kg/100 pc.              |  |
| CO Footprint (GWP) Cradle-to-Gate | 0,1678 kg COe / 1 Piece |  |


# Technical data sheet

## Spacer clip 733 A4

Item number: 1362912



### Dimensions

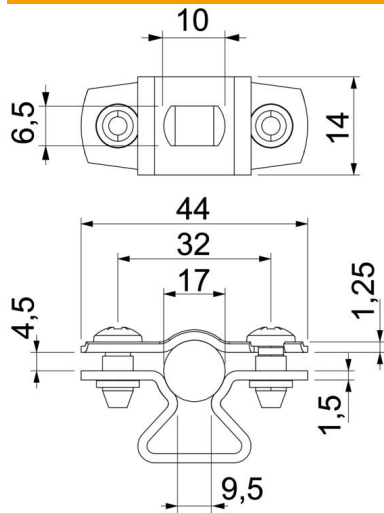

|                   |        |
|-------------------|--------|
| Dimension A       | 44 mm  |
| Dimension B       | 32 mm  |
| Dimension b       | 14 mm  |
| Dimension D       | 17 mm  |
| Dimension d max.  | 17 mm  |
| Dimension d min.  | 14 mm  |
| Dimension L       | 10 mm  |
| Dimension s       | 9.5 mm |
| Dimension t1 (mm) | 1.25   |
| Dimension t2 (mm) | 1.5    |
| Dimension x       | 4.5 mm |

### Technical data

|                                  |            |
|----------------------------------|------------|
| Distance to the wall             | yes        |
| Number of cables/pipes           | 1          |
| Version for                      | Closed     |
| Fastening type                   | Screw hole |
| For diameter                     | 14 - 17    |
| Suitable in fire protection area | no         |
| Halogen-free                     | yes        |
| Plastic-covered                  | no         |
| Material thickness               | 1.5 mm     |
| Clamping range D, max.           | 17 mm      |
| Clamping range D, min.           | 14 mm      |
| UV-resistant                     | yes        |