


Technical data sheet

Spacer clip 733 ALU

Item number: 1362818

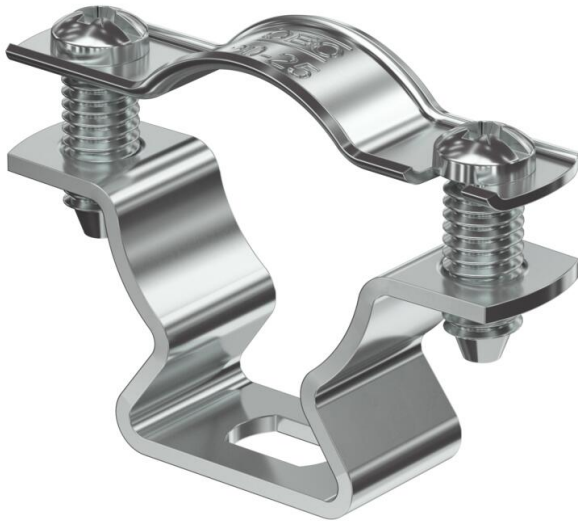

Spacer clip for the installation of pipes and cables on walls, ceilings and floors. With self-locking upper part. Fastening via slot. From the clip size of 20 suitable for installation with a nail device or bolt-firing device.

Approved for the maintenance of electrical function to DIN 4102 Part 12, maintenance of electrical function classes E30 to E90 (except ALU).



Alu

Aluminium

Master data

Item number	1362818
Type	ASL 733 25 ALU
Description 1	Distance saddle
Description 2	with slot
Manufacturer	OBO
Dimension	20-25mm
Material	Aluminium
Smallest sales unit	25
Unit of quantity	Piece
Weight	1.254 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,1632 kg COe / 1 Piece


Technical data sheet

Spacer clip 733 ALU

Item number: 1362818



Dimensions

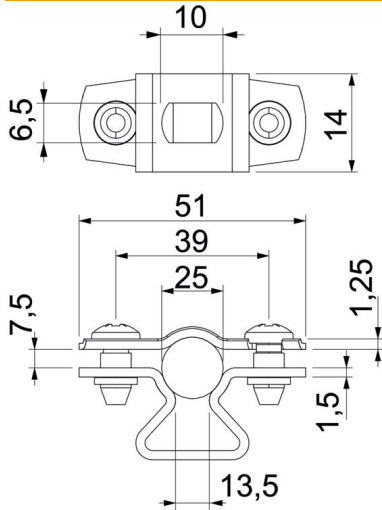

Dimension A	51 mm
Dimension B	39 mm
Dimension b	14 mm
Dimension D	25 mm
Dimension d max.	25 mm
Dimension d min.	20 mm
Dimension L	10 mm
Dimension s	13.5 mm
Dimension t1 (mm)	1.25
Dimension t2 (mm)	1.5
Dimension x	7.5 mm

Technical data

Distance to the wall	yes
Number of cables/pipes	1
Version for	Closed
Fastening type	Screw hole
For diameter	20 - 25
Halogen-free	yes
Plastic-covered	no
Material thickness	1.5 mm
Clamping range D, max.	25 mm
Clamping range D, min.	20 mm
UV-resistant	yes