


# Technical data sheet

## AZ small duct 50 A4

Item number: 6075152

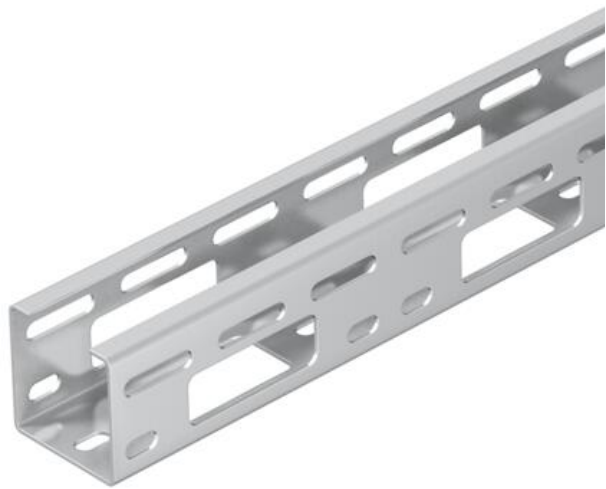

AZ small duct with a side height of 50 mm.  
Magnetic shield insulation without cover 20 dB, with cover 50 dB.



A4	Stainless steel
2B	Bright, treated

Master data		
Item number	6075152	
Description 1	AZ small duct	
Description 2	perforated	
Manufacturer	OBO	
Dimension	50x50x3000	
Colour	stainless steel	
Material	Stainless steel	
Surface	Bright, treated	
Surface standard		
Smallest sales unit	3	
Unit of quantity	Metre	
Weight	135.7 kg	
Weight unit	kg/100 m	
CO Footprint (GWP) Cradle-to-Gate	9,3188 kg COe / 1 Meter	


# Technical data sheet

## AZ small duct 50 A4

Item number: 6075152



### Dimensions

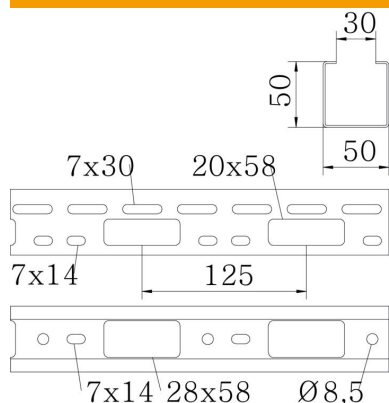


Length	3,000 mm
Width	50 mm
Height	50 mm
Plate thickness	1.5 mm
Dimension B	50 mm

### Technical data

Connector version	Without connectors
Mounting system fastening type	Ceiling Wall
Maintain electrical functions	no
Mounting perforation in base	yes
NATO hole pattern	no
Usable cross-section	25 cm <sup>2</sup>
Usable cross-section	2500 mm <sup>2</sup>
Rustproof steel, pickled	no
Side perforation	yes
Wide-span version	no

### Loads

Insertable support spacings, min.	1 m
Insertable support spacings, max.	3 m
Support spacing 1.0 m	2.5 kN/m
Support spacing 1.5 m	2 kN/m
Support spacing 2.0 m	1.2 kN/m
Support spacing 2.5 m	0.85 kN/m
Support spacing 3.0 m	0.5 kN/m

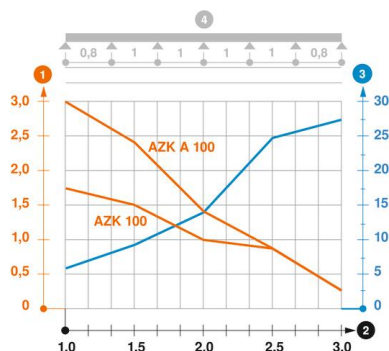

### Load diagram, AZ channel

- 1 Permitted cable tray/ladder load in kN/m without man load
- 2 Support width in m
- 3 Rail bend in mm at permitted kN/m
- 4 Load scheme during testing
- Load curve with cable tray/ladder width in mm
- Strut bend curve according to support width