


Technical data sheet

Beam clamp, vertical BFK 166 FT

Item number: 6003888



Beam clamp for clamping on the steel girder.
The cable support system attached to the beam clamp runs vertically.

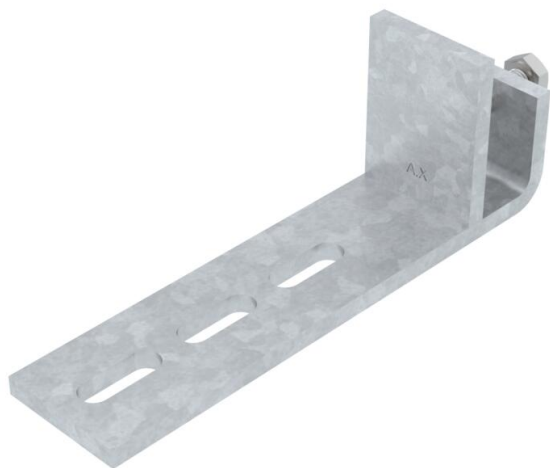

St

Steel

FT

Hot-dip galvanised

Master data

Item number	6003888
Type	BFK 166 58 20 FT
Description 1	Clamping piece
Description 2	for max. supp. thickness 20 mm
Manufacturer	OBO
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	10
Unit of quantity	Piece
Weight	45 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,0369 kg CO2e / 1 Piece


Technical data sheet

Beam clamp, vertical BFK 166 FT

Item number: 6003888



Dimensions

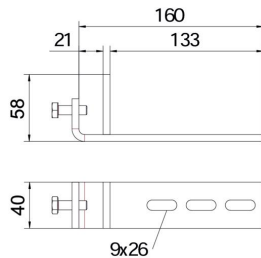

Width	166 mm
Height	20 mm
Dimension B	166 mm
Dimension b	133 mm
Dimension B1	133 mm

Technical data

Version for	Miscellaneous
Suitable for profile shapes	C profile