

Technical data sheet

Flat angle BRA FW 70130, falling

Item number: 6133287



Flat angle, falling, as a fitting for changing the direction of the Signa Style device installation trunking.
Solid fitting for attaching to the wall.



Alu	Aluminium
EL	Anodised

Master data

Item number	6133287
Type	BRA FWF70130 EL
Description 1	Flat angle
Description 2	SIGNA STYLE falling 70x130 ano
Manufacturer	OBO
Dimension	70x130x270
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	94.6 kg
Weight unit	kg/100 pc.


Technical data sheet

Flat angle BRA FW 70130, falling

Item number: 6133287



Dimensions

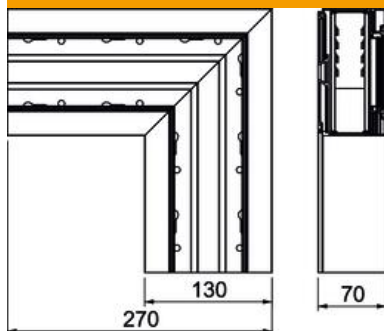

Length	270 mm
Width	130 mm
Height	70 mm

Technical data

Number of covers	1
Version for	Base
for duct width	130 mm
for trunking height	70 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	yes
Cover width	80 mm
Change of direction	Vertical, falling
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK07.
Symmetrical	no
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, min.	90 mm