

Technical data sheet

Flat angle BRA FW 70170, falling

Item number: 6133288



Flat angle, falling, as a fitting for changing the direction of the Signa Style device installation trunking.
Solid fitting for attaching to the wall.



Alu	Aluminium
EL	Anodised

Master data

Item number	6133288
Type	BRA FWF70170 EL
Description 1	Flat angle
Description 2	SIGNA STYLE falling 70x170 ano
Manufacturer	OBO
Dimension	70x170x270
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	99.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	24,8591 kg CO2e / 1 Piece


Technical data sheet

Flat angle BRA FW 70170, falling

Item number: 6133288



Dimensions

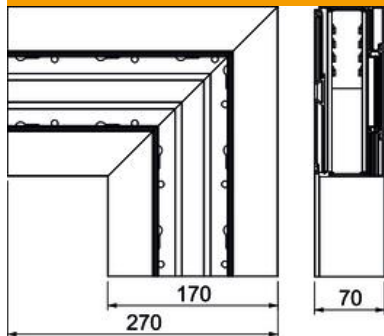

Length	270 mm
Width	170 mm
Height	70 mm

Technical data

Number of covers	1
Version for	Base
for duct width	170 mm
for trunking height	70 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	yes
Cover width	79 mm
Change of direction	Vertical, falling
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK07.
Symmetrical	no
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, min.	90 mm