


Technical data sheet

External corner Signa Base AE 70110

Item number: 6132741



External corner as a fitting for changing the direction of the Signa Base device installation trunking.
Cut-concealing external corner for snapping onto the base. Angle adjustable.

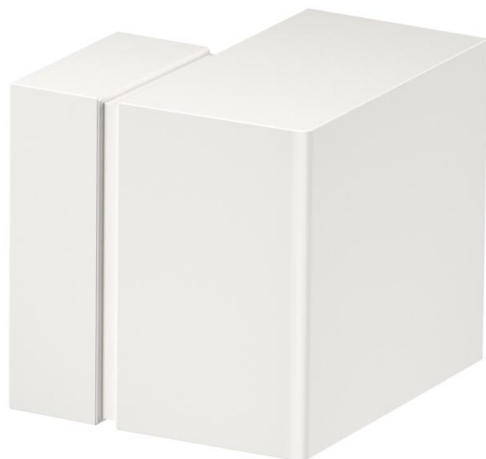

Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6132741
Type	BRK AE70110 rws
Description 1	External corner
Description 2	SIGNA BASE 70x110 9010
Manufacturer	OBO
Dimension	119x137x120
Colour	Pure white; RAL 9010
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	1
Unit of quantity	Piece
Weight	16.2 kg
Weight unit	kg/100 pc.


Technical data sheet

External corner Signa Base AE 70110

Item number: 6132741



Dimensions

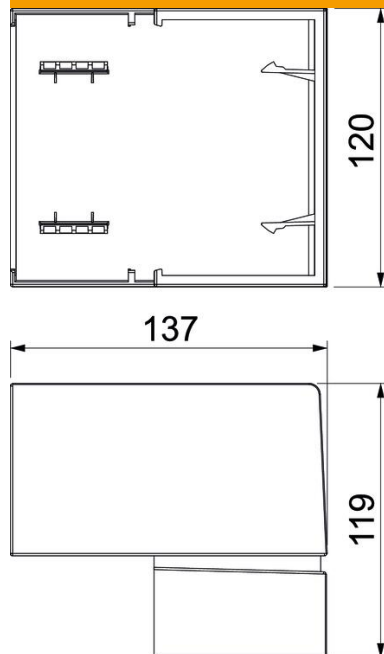

Length	119 mm
Width	137 mm
Height	120 mm

Technical data

Version for	Hood fitting
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Cross-over
Mounting perforation in base	no
Protection rating	IP40
Protective film	no
Protection rating IK code	IK07.
Symmetrical	no
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	93 mm
Angle range, min.	85 mm