

Technical data sheet

External corner Signa Base AE 70170

Item number: 6132747



External corner as a fitting for changing the direction of the Signa Base device installation trunking.
Cut-concealing external corner for snapping onto the base. Angle adjustable.



Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6132747
Type	BRK AE70170 cws
Description 1	External corner
Description 2	SIGNA BASE 70x170 9001
Manufacturer	OBO
Colour	Cream; RAL 9001
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	1
Unit of quantity	Piece
Weight	23.97 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,2938 kg CO2e / 1 Piece


Technical data sheet

External corner Signa Base AE 70170

Item number: 6132747



Dimensions

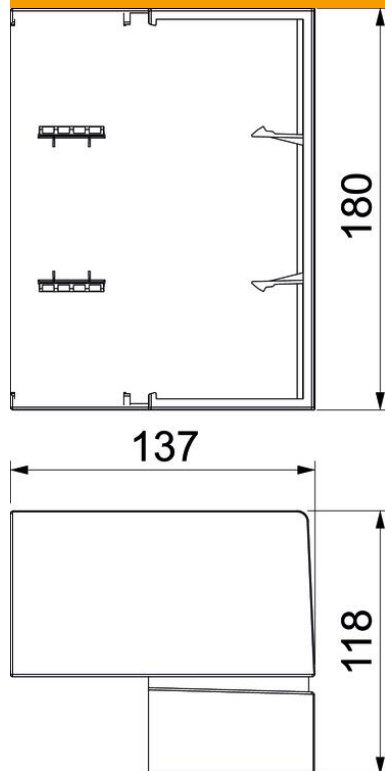

Length	118 mm
Width	137 mm
Height	180 mm

Technical data

Version for	Hood fitting
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Cross-over
Mounting perforation in base	no
Protection rating	IP40
Protective film	no
Protection rating IK code	IK07.
Symmetrical	no
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	93 mm
Angle range, min.	85 mm