

# Technical data sheet

## Flat angle Signa Base FW 70110

Item number: 6132762



Cut-concealing flat angle hood fitting for SIGNA BASE breastwork trunking. Material: PC+ABS, halogen-free.

Cut-concealing flat angle for snapping onto the base.



Polycarbonate/Acrylnitrile-butadiene-styrene

### Master data

|                                    |                                              |
|------------------------------------|----------------------------------------------|
| Item number                        | 6132762                                      |
| Type                               | BRK FW70110 cws                              |
| Description 1                      | Flat angle                                   |
| Description 2                      | SIGNA BASE 70x110 9001                       |
| Manufacturer                       | OBO                                          |
| Colour                             | Cream; RAL 9001                              |
| Material                           | Polycarbonate/Acrylnitrile-butadiene-styrene |
| Smallest sales unit                | 1                                            |
| Unit of quantity                   | Piece                                        |
| Weight                             | 14 kg                                        |
| Weight unit                        | kg/100 pc.                                   |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,9531 kg CO2e / 1 Piece                     |


# Technical data sheet

## Flat angle Signa Base FW 70110

Item number: 6132762



### Dimensions

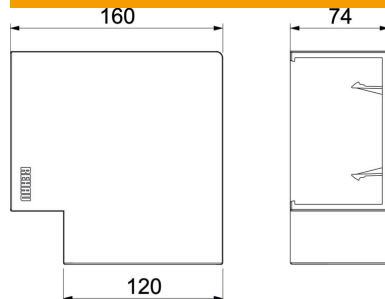

|        |        |
|--------|--------|
| Length | 160 mm |
| Width  | 160 mm |
| Height | 74 mm  |

### Technical data

|                                   |                          |
|-----------------------------------|--------------------------|
| Version for                       | Hood fitting             |
| for duct width                    | 110 mm                   |
| for trunking height               | 70 mm                    |
| Halogen-free                      | yes                      |
| Cable retaining clip              | no                       |
| Duct connector                    | no                       |
| Cover mounting type               | Cross-over               |
| Mounting perforation in base      | no                       |
| Change of direction               | Vertical, rising/falling |
| Protection rating                 | IP40                     |
| Protective film                   | no                       |
| Protection rating IK code         | IK07.                    |
| Symmetrical                       | yes                      |
| Permitted temperature range, max. | 60 °C                    |
| Permitted temperature range, min. | -5 °C                    |
| Angle range, min.                 | 90 mm                    |