

Technical data sheet

Flat angle Signa Base FW 70130

Item number: 6132765



Flat angle as a fitting for changing the direction of the Signa Base device installation trunking.
Cut-concealing flat angle for snapping onto the base.



PC/ABS

Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6132765
Type	BRK FW70130 cws
Description 1	Flat angle
Description 2	SIGNA BASE 70x130 9001
Manufacturer	OBO
Colour	Cream; RAL 9001
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	1
Unit of quantity	Piece
Weight	16.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,132 kg CO2e / 1 Piece


Technical data sheet

Flat angle Signa Base FW 70130

Item number: 6132765



Dimensions

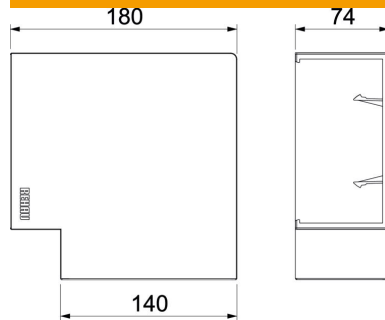

Length	180 mm
Width	180 mm
Height	74 mm

Technical data

Version for	Hood fitting
for duct width	130 mm
for trunking height	70 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Cross-over
Mounting perforation in base	no
Change of direction	Vertical, rising/falling
Protection rating	IP40
Protective film	no
Protection rating IK code	IK07.
Symmetrical	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, min.	90 mm