

Technical data sheet

Flat angle Signa Base FW 70130

Item number: 6132766



Flat angle as a fitting for changing the direction of the Signa Base device installation trunking.
Cut-concealing flat angle for snapping onto the base.



Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6132766
Type	BRK FW70130 rws
Description 1	Flat angle
Description 2	SIGNA BASE 70x130 9010
Manufacturer	OBO
Dimension	180x180x74
Colour	Pure white; RAL 9010
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	1
Unit of quantity	Piece
Weight	16.5 kg
Weight unit	kg/100 pc.


Technical data sheet

Flat angle Signa Base FW 70130

Item number: 6132766



Dimensions

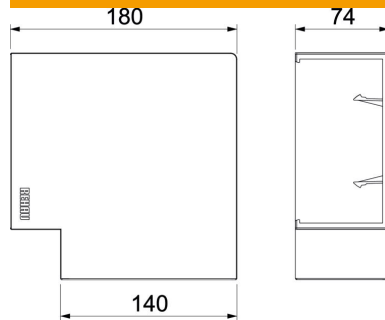

Length	180 mm
Width	180 mm
Height	74 mm

Technical data

Version for	Hood fitting
for duct width	130 mm
for trunking height	70 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Cross-over
Mounting perforation in base	no
Change of direction	Vertical, rising/falling
Protection rating	IP40
Protective film	no
Protection rating IK code	IK07.
Symmetrical	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, min.	90 mm