


# Technical data sheet

## Internal corner Signa Base IE 70130

Item number: 6132754



Internal corner as a fitting for changing the direction of the Signa Base device installation trunking.  
Internal corner for snapping on to the base to conceal cuts. Angle adjustable.

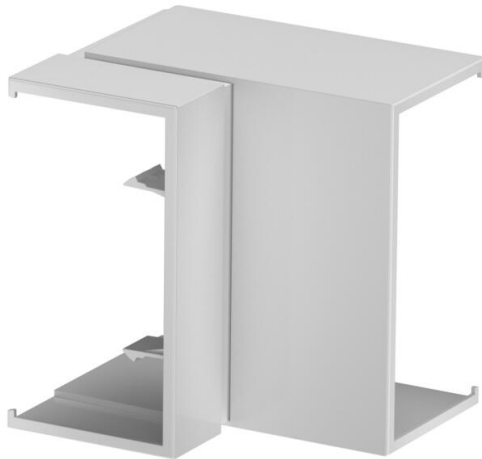

Polycarbonate/Acrylnitrile-butadiene-styrene

### Master data

|                     |                                              |
|---------------------|----------------------------------------------|
| Item number         | 6132754                                      |
| Type                | BRK IE70130 lgr                              |
| Description 1       | Internal corner                              |
| Description 2       | SIGNA BASE 70x130 7035                       |
| Manufacturer        | OBO                                          |
| Colour              | Light grey; RAL 7035                         |
| Material            | Polycarbonate/Acrylnitrile-butadiene-styrene |
| Smallest sales unit | 1                                            |
| Unit of quantity    | Piece                                        |
| Weight              | 14.21 kg                                     |
| Weight unit         | kg/100 pc.                                   |


# Technical data sheet

## Internal corner Signa Base IE 70130

Item number: 6132754



### Dimensions

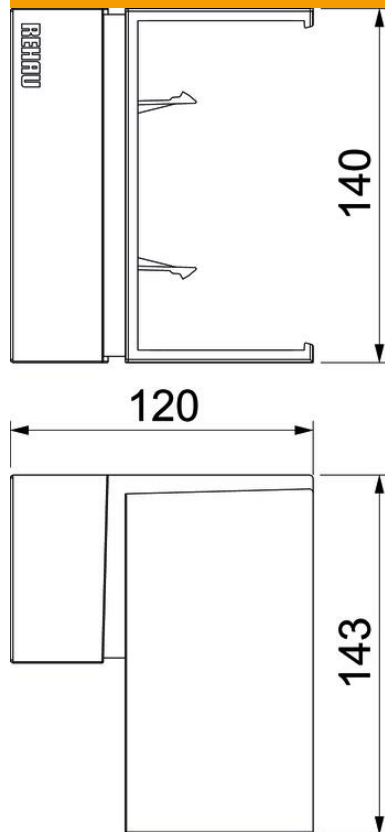

|        |        |
|--------|--------|
| Length | 120 mm |
| Width  | 143 mm |
| Height | 140 mm |

### Technical data

|                                   |              |
|-----------------------------------|--------------|
| Number of covers                  | 0            |
| Version for                       | Hood fitting |
| Shape                             | Asymmetrical |
| Halogen-free                      | yes          |
| Cable retaining clip              | no           |
| Duct connector                    | no           |
| Cover mounting type               | Cross-over   |
| Mounting perforation in base      | no           |
| Protection rating                 | IP40         |
| Protective film                   | no           |
| Protection rating IK code         | IK07.        |
| Permitted temperature range, max. | 60 °C        |
| Permitted temperature range, min. | -5 °C        |
| Angle range, max.                 | 93 mm        |
| Angle range, min.                 | 85 mm        |