

Technical data sheet

Internal corner Signa Base IE 70170

Item number: 6132755



Internal corner as a fitting for changing the direction of the Signa Base device installation trunking.
Internal corner for snapping on to the base to conceal cuts. Angle adjustable.



PC/ABS Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6132755
Type	BRK IE70170 cws
Description 1	Internal corner
Description 2	SIGNA BASE 70x170 9001
Manufacturer	OBO
Colour	Cream; RAL 9001
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	1
Unit of quantity	Piece
Weight	15.55 kg
Weight unit	kg/100 pc.


Technical data sheet

Internal corner Signa Base IE 70170

Item number: 6132755



Dimensions

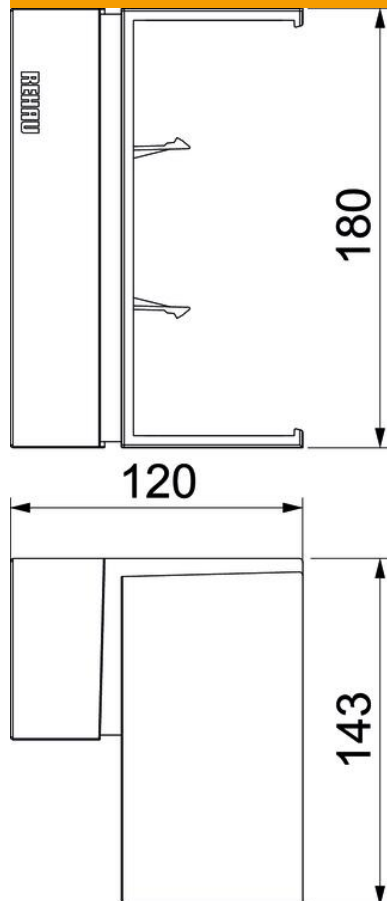

Length	120 mm
Width	143 mm
Height	180 mm

Technical data sheet

Internal corner Signa Base IE 70170

Item number: 6132755



Technical data

Number of covers	0
Version for	Hood fitting
Shape	Asymmetrical
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Cross-over
Mounting perforation in base	no
Protection rating	IP40
Protective film	no
Protection rating IK code	IK07.
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	93 mm
Angle range, min.	85 mm