

Technical data sheet

Joint cover Signa Base SSA 70110

Item number: 6132787



Joint cover to connect the Signa Base device installation trunking.



PC/ABS

Polycarbonate/Acrylnitrile-butadiene-styrene

Master data		
Item number	6132787	
Type	BRK SSA70110 cws	
Description 1	Joint cover	
Description 2	SIGNA BASE 70x110 9001	
Manufacturer	OBO	
Colour	Cream; RAL 9001	
Material	Polycarbonate/Acrylnitrile-butadiene-styrene	
Smallest sales unit	10	
Unit of quantity	Piece	
Weight	2.67 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,1585 kg CO2e / 1 Piece	


Technical data sheet

Joint cover Signa Base SSA 70110

Item number: 6132787



Dimensions

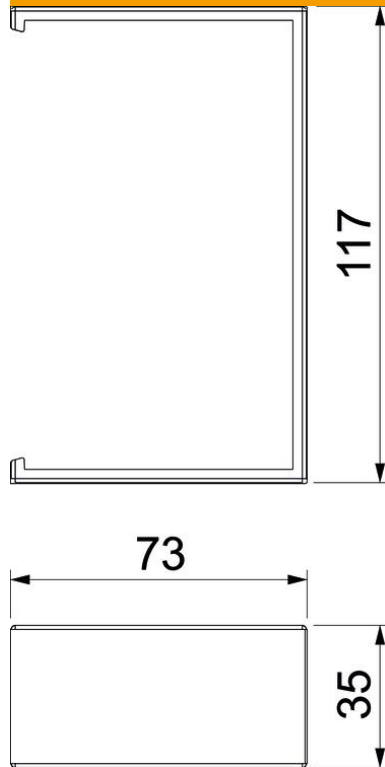

Length	35 mm
Width	117 mm
Height	73 mm

Technical data

Version for	Trunking cut cover
Fastening type	Self-adhesive
Shape	Symmetrical
Halogen-free	yes
Cover width	80 mm
Protection rating	IP40
Protection rating IK code	IK07.
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C