

Technical data sheet

Clamp clip 2056 H-foot, 1-fold, plastic pressure sleeve, FT

Item number: 1186297



Clamp clip with hammerhead foot, plastic pressure sleeve made of polypropylene. For vertical and horizontal mounting of 1 single cable on a C-profile rail. For a slot width 16–17 mm. With 1-start screw thread on pressure sleeve, universal hexagonal screw head WAF10, with slot and cross recess. Suitable for assembly indoors and outdoors. We recommend the use of a counter-sleeve.



St

Steel

FT

Hot-dip galvanised

Master data

Item number	1186297
Type	BS-H1-K-100 FT
Description 1	Clamp clip 2056
Manufacturer	OBO
Dimension	90-100mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	25
Unit of quantity	Piece
Weight	27.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,6593 kg COe / 1 Piece


Technical data sheet

Clamp clip 2056 H-foot, 1-fold, plastic pressure sleeve, FT

Item number: 1186297



Dimensions

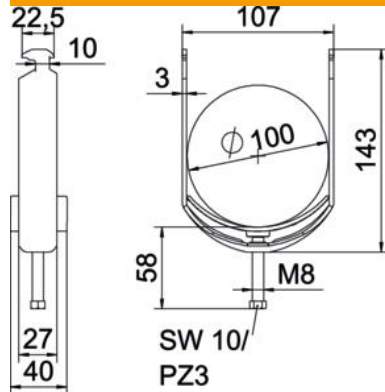

Length	27 mm
Width	107 mm
Height	143 mm
Plate thickness	3 mm
Dimension A	27 mm
Dimension B	107 mm
Dimension C	40 mm
Dimension G (mm)	M8
Dimension H	143 mm
Dimension L	58 mm
Dimension t	3 mm

Technical data

Number of cables/pipes	1
For pipe diameter, max.	100 mm
For pipe diameter, min.	90 mm
for rail with slot width (with interval), max.	17 mm
for rail with slot width (with interval), min.	16 mm
Thread	M8
Halogen-free	yes
Length of external dimensions	40 mm
Max. Tightening torque	5 Nm
With plastic trough	yes
Mounting type	Profile rail
Slot width	10 mm
Clamping range D, max.	100 mm
Clamping range D, min.	90 mm
Surface addition	hot galvanised
Material addition	Steel
With counter-trough	no
Material of trough	Plastic
Material quality of trough	Polypropylene