

# Technical data sheet

## Clamp clip 2056 H-foot, 1-fold, plastic pressure sleeve, FT

Item number: 1186242



Clamp clip with hammerhead foot, plastic pressure sleeve made of polypropylene. For vertical and horizontal mounting of 1 single cable on a C-profile rail. For a slot width 16–17 mm. With 1-start screw thread on pressure sleeve, universal hexagonal screw head WAF10, with slot and cross recess. Suitable for assembly indoors and outdoors. We recommend the use of a counter-sleeve.



St

Steel

FT

Hot-dip galvanised

### Master data

|                                    |                         |
|------------------------------------|-------------------------|
| Item number                        | 1186242                 |
| Type                               | BS-H1-K-46 FT           |
| Description 1                      | Clamp clip 2056         |
| Manufacturer                       | OBO                     |
| Dimension                          | 40-46mm                 |
| Material                           | Steel                   |
| Surface                            | Hot-dip galvanised      |
| Surface standard                   | DIN EN ISO 1461         |
| Smallest sales unit                | 100                     |
| Unit of quantity                   | Piece                   |
| Weight                             | 10.9 kg                 |
| Weight unit                        | kg/100 pc.              |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,2119 kg COe / 1 Piece |


# Technical data sheet

Clamp clip 2056 H-foot, 1-fold, plastic pressure sleeve, FT

Item number: 1186242



## Dimensions

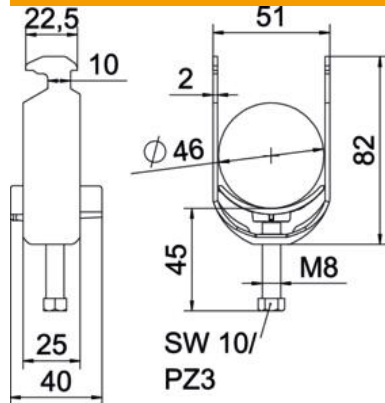

|                  |       |
|------------------|-------|
| Length           | 25 mm |
| Width            | 51 mm |
| Height           | 82 mm |
| Plate thickness  | 2 mm  |
| Dimension A      | 25 mm |
| Dimension B      | 51 mm |
| Dimension C      | 40 mm |
| Dimension G (mm) | M8    |
| Dimension H      | 82 mm |
| Dimension L      | 45 mm |
| Dimension t      | 2 mm  |

## Technical data

|                                                |                |
|------------------------------------------------|----------------|
| Number of cables/pipes                         | 1              |
| For pipe diameter, max.                        | 46 mm          |
| For pipe diameter, min.                        | 40 mm          |
| for rail with slot width (with interval), max. | 17 mm          |
| for rail with slot width (with interval), min. | 16 mm          |
| Thread                                         | M8             |
| Halogen-free                                   | yes            |
| Length of external dimensions                  | 40 mm          |
| Max. Tightening torque                         | 5 Nm           |
| With plastic trough                            | yes            |
| Mounting type                                  | Profile rail   |
| Slot width                                     | 10 mm          |
| Clamping range D, max.                         | 46 mm          |
| Clamping range D, min.                         | 40 mm          |
| Surface addition                               | hot galvanised |
| Material addition                              | Steel          |
| With counter-trough                            | no             |
| Material of trough                             | Plastic        |
| Material quality of trough                     | Polypropylene  |