

Technical data sheet

T piece for PYROLINE® Con S BSKH09-K0511 fire protection duct

Item number: 7215637



T piece for PYROLINE® Con S fire protection duct, type BSKH09-K0511, consisting of fibreglass lightweight concrete which is resistant to water and frost, for the creation of T branches of the duct. Mounted connectors ensure quick mounting in situ, whilst loosely placed covers ensure quick inspection and reassignment.

Including connection screws and sealing strips.

Including connection screws and sealing strip.



Fibreglass lightweight concrete

Master data

Item number	7215637
Type	BSKH09-T0511
Description 1	T piece
Description 2	for BSKH09-K0511
Manufacturer	OBO
Dimension	50x110
Colour	Grey
Material	Fibreglass lightweight concrete
Smallest sales unit	1
Unit of quantity	Piece
Weight	1175 kg
Weight unit	kg/100 pc.


Technical data sheet

T piece for PYROLINE® Con S BSKH09-K0511 fire protection duct

Item number: 7215637



Dimensions

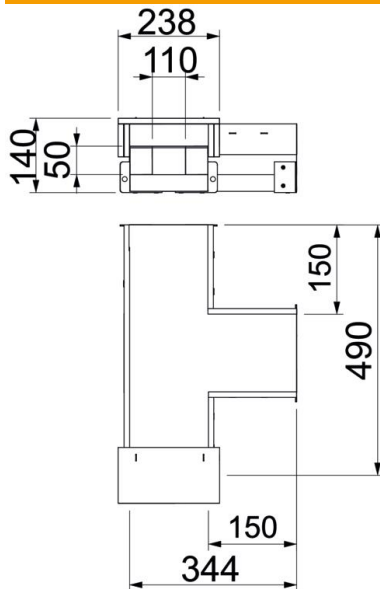

External dimensions	238 x 140
Internal dimensions	110 x 50
Length	540 mm
Width	354 mm
Height	140 mm
Dimension B	238 mm
Dimension b	110 mm
Dimension h	50 mm
Dimension H	140 mm
Dimension L	490 mm
Dimension I	344 mm

Technical data

Number of flammable sides	4
Fire resistance class E – function maintenance	30
Fire resistance class I – installation duct	90
With perforation	no
Partitions possible	yes
Jacketing	Without
Material of the insulation	Glass-fibre lightweight concrete