


Technical data sheet

Connection adapter, straight, socket part

Item number: 6117191



Connector part adapter, straight, for connection to an STD-D0C / STD-D3C or STD-F0C / STD-F3C socket from the side, for VL extension cable with Wieland connector GST 18i 3p.

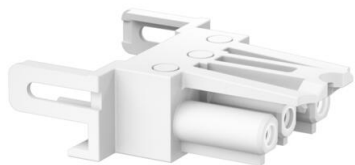

PA

 Polyamide

Master data		
Item number	6117191	
Type	BTa-SKS S1 W	
Description 1	Socket part adapter, straight	
Description 2	GST 18i 3p, Modul 45connect	
Manufacturer	OBO	
Colour	White	
Material	Polyamide	
Smallest sales unit	10	
Unit of quantity	Piece	
Weight	1.2 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,0513 kg CO2e / 1 Piece	


Technical data sheet

Connection adapter, straight, socket part


Item number: 6117191



Dimensions

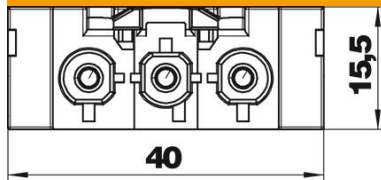

Length	54 mm
Width	40 mm
Height	15.5 mm

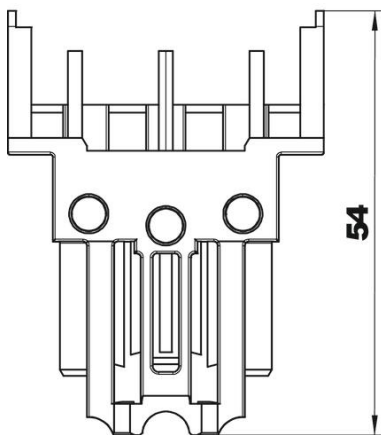

Technical data

Type of locking	Integrated in plug connector
Version of the device connection	socket
Built-in variants	Installation part/plug connection
Colour of the coding/contact insert	White
Colour of the separate adapter	White
Thread connection dimension	No threaded connection
Halogen-free	yes
Contact material	CuZn
Mechanical encoding	yes
Angle of inclination, max.	0 °
Angle of inclination, min.	0 °
Nominal voltage	250 V
Nominal current	16 A
Surface treatment of the contacts	Tin-plated
Pin labelling	L, N, PE
Pole number	3
Protection rating	IP20
Direction of insertion	Straight
Plug-in system	GST18