


Technical data sheet

Mounting angle BW 80

Item number: 6019528

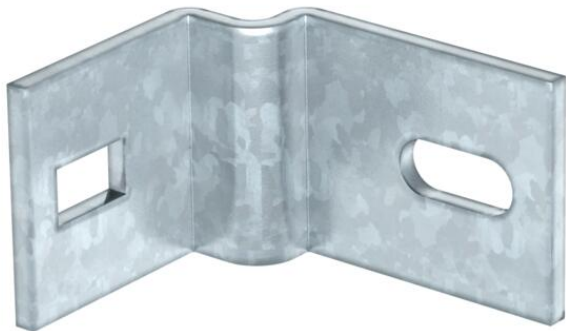

Mounting angle for mounting IS 8 supports on the wall.
The mounting angle can also be used in conjunction with the heavy-duty vertical ladder, type SLS 80.
Including fastening bolt M12x30.
Including truss-head bolt M12 x 30.



St

Steel

FT

Hot-dip galvanised

Master data

Item number	6019528
Description 1	Fastening bracket
Description 2	for IS 8 support
Manufacturer	OBO
Dimension	80x65
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	10
Unit of quantity	Piece
Weight	32.9 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,744 kg COe / 1 Piece


Technical data sheet

Mounting angle BW 80

Item number: 6019528



Dimensions

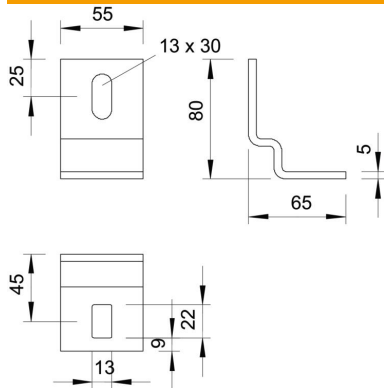

Length	80 mm
Width	55 mm
Height	65 mm

Technical data

Version for	Fastening bracket
Maintain electrical functions	yes
Suitable for profile shapes	I profile
With screw accessories	yes
Adjustable	no