


Technical data sheet

Rung CKD 40

Item number: 6008269



CKD40 rung for use in heavy-duty vertical ladders and in IS 8 supports.
The maximum rung load is 175 kg.

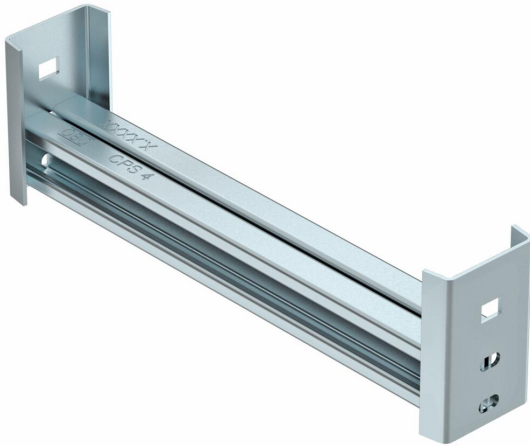

St	Steel
FT	Hot-dip galvanised

Master data

Item number	6008269
Type	CKD 40 60 FT
Description 1	C-frame
Description 2	for IS 8 support
Manufacturer	OBO
Dimension	B554mm
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	211 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	4,5105 kg CO2e / 1 Piece


Technical data sheet

Rung CKD 40

Item number: 6008269



Dimensions

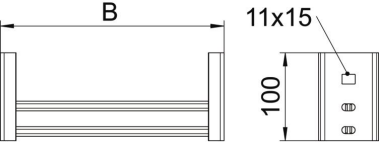

lampDimension WxH	2 x 40 x 22,5 mm
Length	554 mm
Width	554 mm
Height	100 mm



Technical data

Material thickness	2 mm
Slot width	18 mm