


Technical data sheet

Rung CKD 40

Item number: 6008277



CKD40 rung for use in heavy-duty vertical ladders and in IS 8 supports.
The maximum rung load is 175 kg.

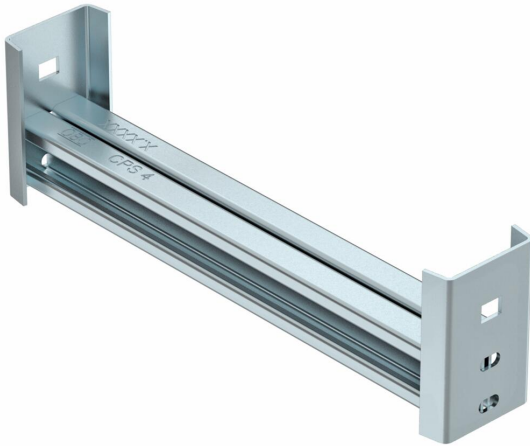

St	Steel
FT	Hot-dip galvanised

Master data


 
Item number	6008277
Type	CKD 40 70 FT
Description 1	C-frame
Description 2	for IS 8 support
Manufacturer	OBO
Dimension	B654mm
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	243 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	5,2822 kg CO2e / 1 Piece

Technical data sheet

Rung CKD 40

Item number: 6008277

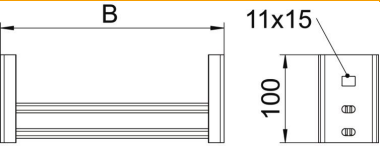

Dimensions		
	lampDimension WxH	2 x 40 x 22,5 mm
	Length	654 mm
	Width	654 mm
	Height	100 mm
Technical data		
	Material thickness	2 mm
	Slot width	18 mm