


Technical data sheet

Rung CKD 40

Item number: 6008293



CKD40 rung for use in heavy-duty vertical ladders and in IS 8 supports.
The maximum rung load is 175 kg.

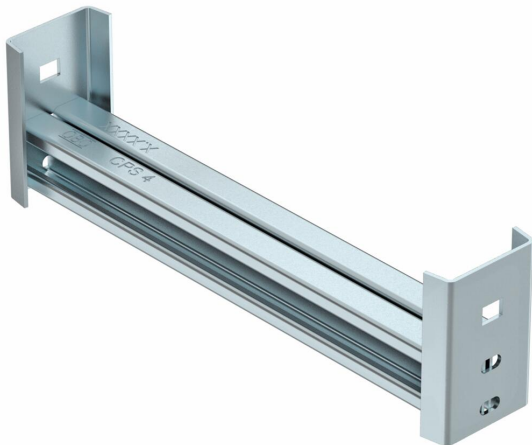

St

Steel

FT

Hot-dip galvanised

Master data		
Item number	6008293	
Type	CKD 40 90 FT	
Description 1	C-frame	
Description 2	for IS 8 support	
Manufacturer	OBO	
Dimension	B854mm	
Colour	zinc	
Material	Steel	
Surface	Hot-dip galvanised	
Surface standard	DIN EN ISO 1461	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	307 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	6,559 kg CO2e / 1 Piece	

Technical data sheet

Rung CKD 40

Item number: 6008293



Dimensions		
	lampDimension WxH	2 x 40 x 22,5 mm
	Length	854 mm
	Width	854 mm
	Height	100 mm
Technical data		
	Material thickness	2 mm
	Slot width	18 mm